


# E11550



## Wirable plug

SSTGF030MSSFPKG

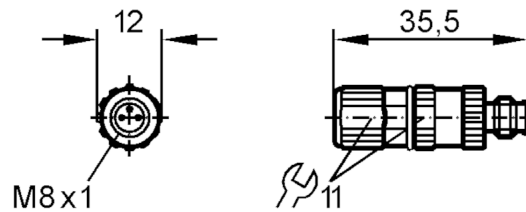

### Electrical data

Operating voltage	[M]	< 50 AC / < 75 DC
Protection class		III
Max. current load total	[A]	4

### Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

### Mechanical data

Weight	[g]	14.8
Materials		PA
Material nut		brass, nickel-plated

### Remarks

Pack quantity		1 pcs.
---------------	--	--------

### Electrical connection

insulation displacement technology: 0.14...0.38 mm<sup>2</sup>; Core insulation: PVC, TPE; (Ø 1.0...1.6 mm); Cable sheath: Ø 3...5 mm

### Electrical connection - plug

Connector: 1 x M8, straight; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated



# E11550

## Wirable plug

SSTGF030MSSFPKG



### Connection

