

# E11059




## Connecting cable with socket

ADOAG030--S0002A03

Article no longer available - archive entry

Alternative articles: E10197  
When selecting an alternative article and accessories please note that technical data may differ!

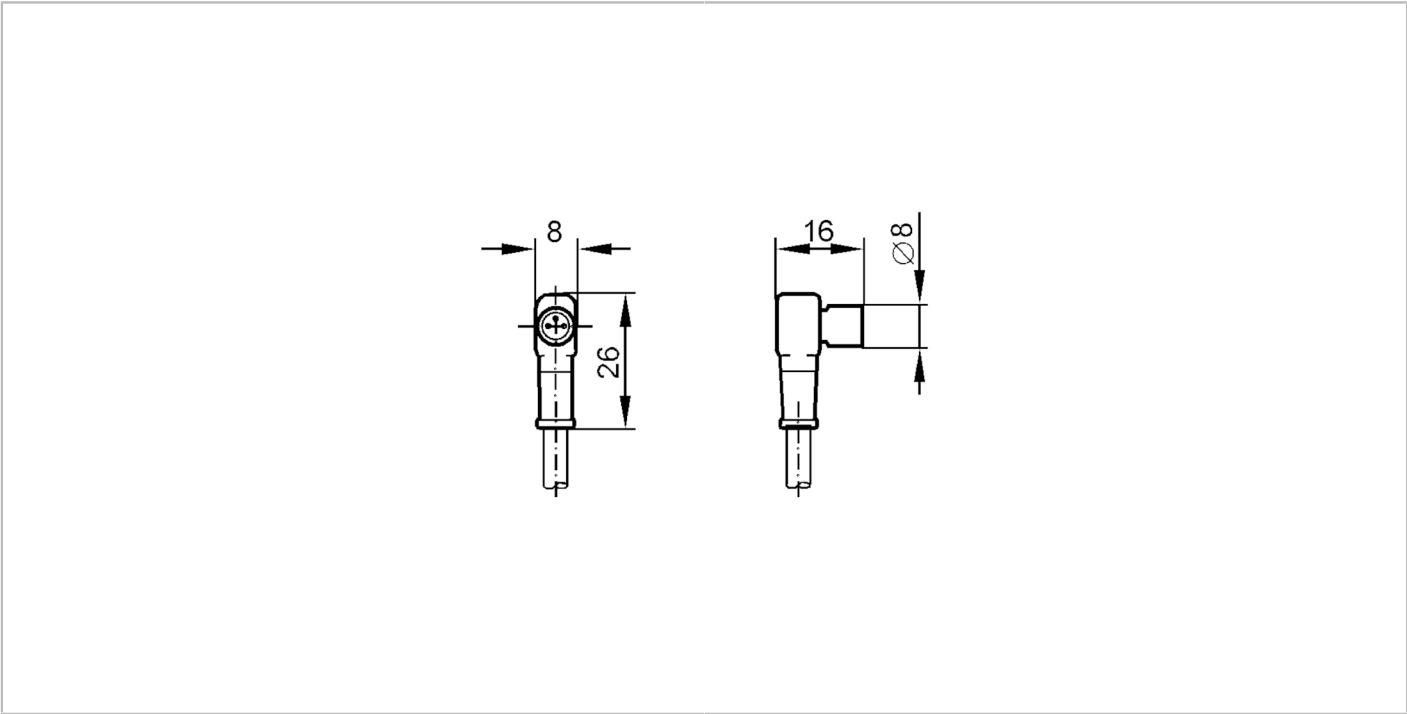

| Electrical data       |      |                   |
|-----------------------|------|-------------------|
| Operating voltage     | [V]  | < 60 AC / < 75 DC |
| Operating conditions  |      |                   |
| Ambient temperature   | [°C] | -25...90          |
| Protection            |      | IP 65             |
| Mechanical data       |      |                   |
| Dimensions            | [mm] | 26 x 8 x 16       |
| Materials             |      | TPU               |
| Moulded-body material |      | TPU               |
| Remarks               |      |                   |
| Pack quantity         |      | 1 pcs.            |

# E11059



## Connecting cable with socket

ADOAG030--S0002A03


### Electrical connection

Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )


### Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU; Locking: snap-in

Connector: 1 x M8, angled; coding: A; Moulded body: TPU; Locking: snap-in

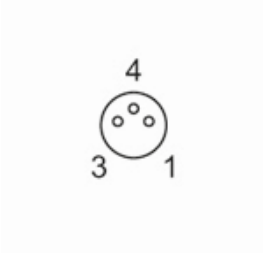

### Connection

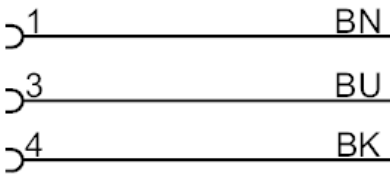

BN = Core colours : brown  
BK = black  
BU = blue