

E11095




Connecting cable with socket

ADOGF030VAS0005E03

Article no longer available - archive entry

Alternative articles: E11495

When selecting an alternative article and accessories please note that technical data may differ!

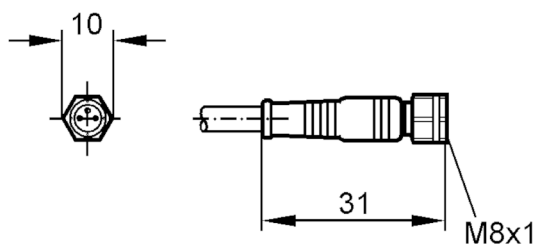

Electrical data

Operating voltage [V] < 60 AC / < 75 DC

Protection class III

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67; (if screwed on)

Mechanical data

Dimensions [mm] 10 x 10 x 31

Materials TPU

Moulded-body material TPU

Material nut stainless steel (1.4305 / 303)

Remarks

Pack quantity 1 pcs.

E11095



Connecting cable with socket

ADOGF030VAS0005E03

Electrical connection


Cable: 5 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: stainless steel (1.4305 / 303)



Connection

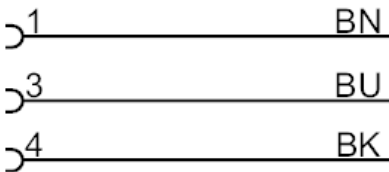

BN = Core colours :
brown
BK = black
BU = blue