

E11129




Connecting cable with socket

ADOAF030MSS0005X03

Article no longer available - archive entry

Alternative articles: E11239

When selecting an alternative article and accessories please note that technical data may differ!

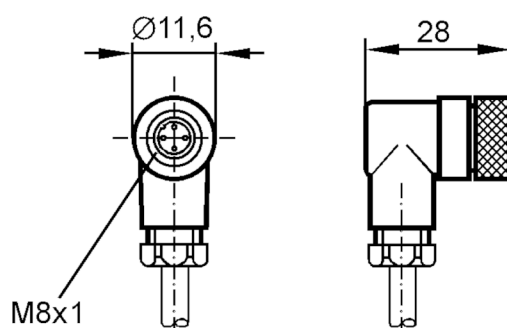

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 67

Mechanical data

Materials	PBT; PA
Moulded-body material	PBT / PA
Material nut	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E11129



Connecting cable with socket

 
ADOAF030MSS0005X03

Electrical connection


Cable: 5 m, PTFE; 3 x 0.38 mm²

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PBT / PA; Locking: brass, nickel-plated



Connection

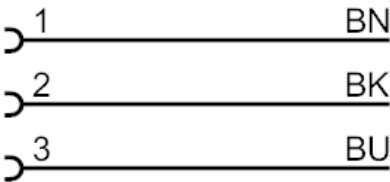

BN =	Core colours :
BK =	brown
BU =	black
	blue