


E11145



Wirable socket

SDOGH040PLSFKSK

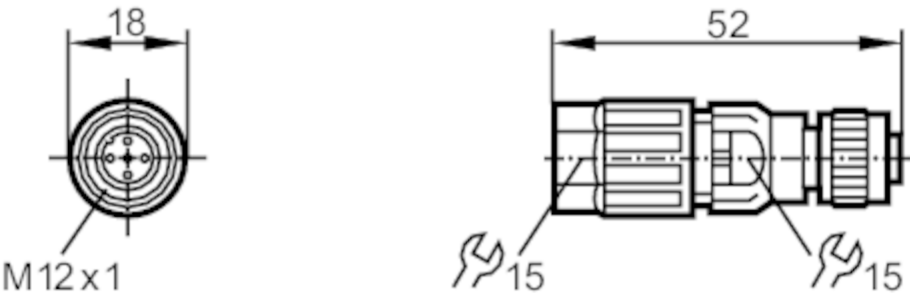

Electrical data

Operating voltage	[V]	< 45 AC / < 70 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...60
Protection		IP 67

Mechanical data

Weight	[g]	13.5
Dimensions	[mm]	18 x 18 x 52
Materials		PA 6.6
Moulded-body material		PA 6.6
Material nut		PA 6.6

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

insulation displacement technology: 0.34...0.75 mm²; Core insulation: PVC / PE; (Ø ...2.5 mm); Cable sheath: Ø 4...7.5 mm

Electrical connection - socket

 Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6; Locking: PA 6.6



E11145

Wirable socket

SDOGH040PLSFKSK



Connection

