


# E12513



## Connecting cable with plug

ASTGN040ZDS0020L04

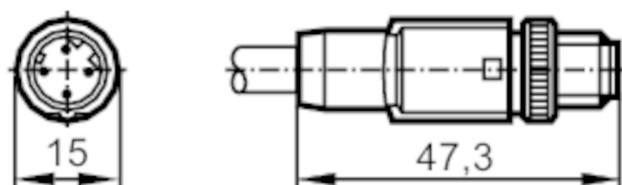

### Application

|                 |                         |
|-----------------|-------------------------|
| Special feature | Gold-plated contacts    |
| Design          | Ethernet cable, D-coded |

### Electrical data

|                         |     |             |
|-------------------------|-----|-------------|
| Operating voltage       | [V] | < 250 AC/DC |
| Max. current load total | [A] | 4           |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -40...70 |
| Protection          |      | IP 67    |

### Mechanical data

|                       |      |                             |
|-----------------------|------|-----------------------------|
| Weight                | [g]  | 1380.5                      |
| Dimensions            | [mm] | 15 x 15 x 47.3              |
| Materials             |      | TPU                         |
| Moulded-body material |      | TPU                         |
| Material nut          |      | diecast zinc, nickel-plated |

### Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

# E12513



## Connecting cable with plug

ASTGN040ZDS0020L04

### Electrical connection


Cable: 20 m, PVC, green, Ø 6.5 mm; 4 x 0.34 mm<sup>2</sup>

### Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected



### Connection

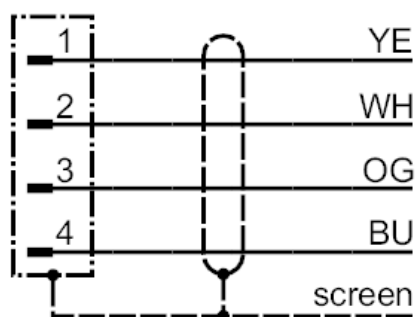

|      |                |
|------|----------------|
| BU = | Core colours : |
| OG = | blue           |
| WH = | orange         |
| YE = | white          |
|      | yellow         |