


E12358



Adapter plug

ESTGH040PLS00,5E04 (PG11)

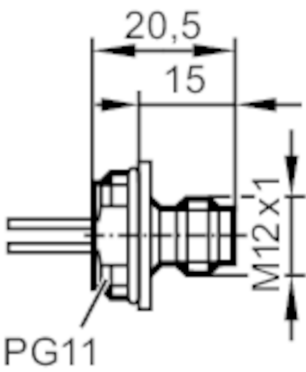

1 O-ring



Electrical data		
Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4; (...40 °C)
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Weight	[g]	9.66
Mounting thread		PG 11
Materials		PA 6.6
Moulded-body material		PA 6.6
Remarks		
Pack quantity		1 pcs.

E12358



Adapter plug

ESTGH040PLS00,5E04 (PG11)

Electrical connection

Cable: 0.5 m, PVC; 4 x 0.25 mm²

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6



Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white