




Fibre optic diffuse reflection sensor

FT-00-M-V-E1/2,5M

Article no longer available - archive entry

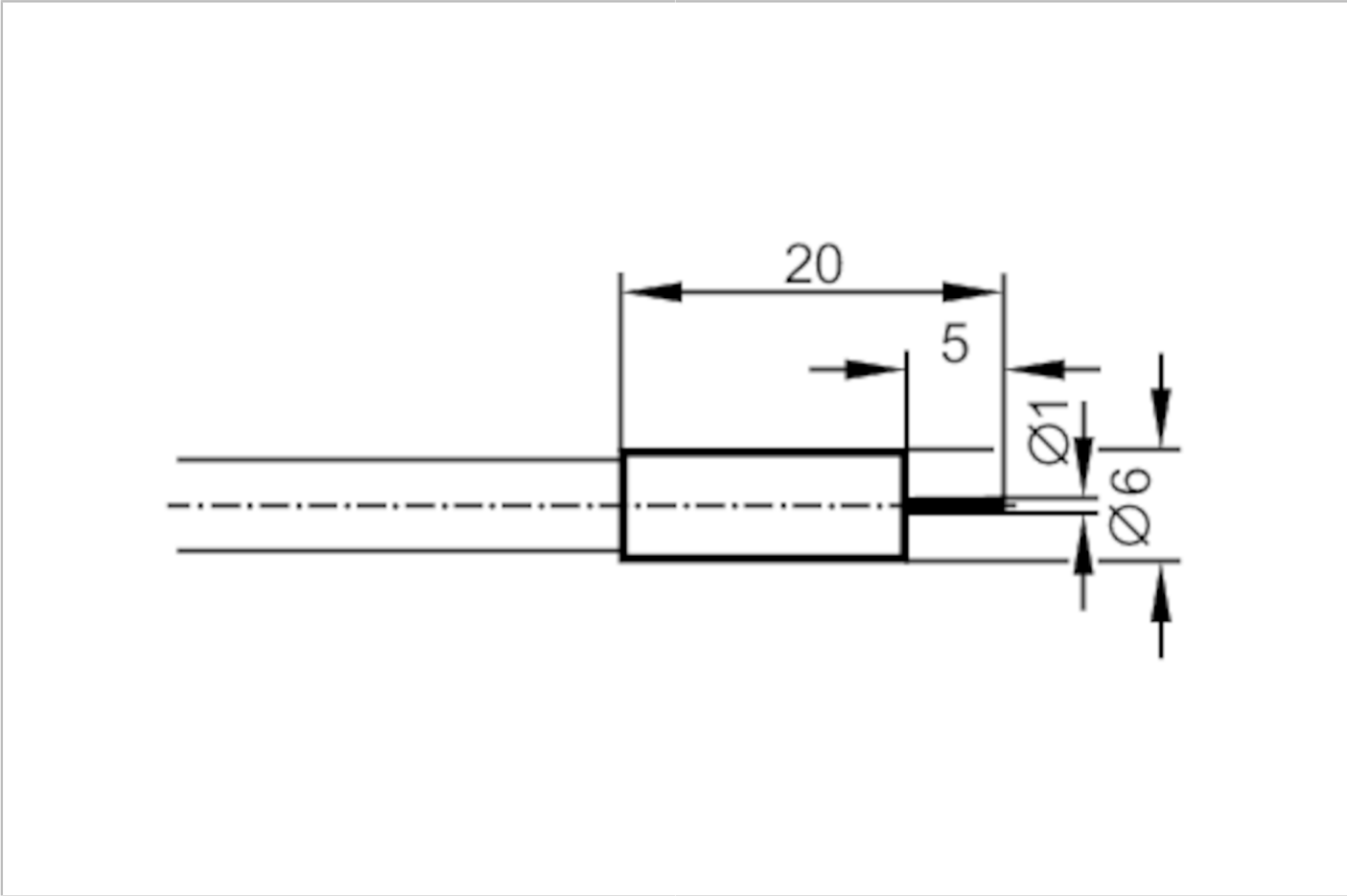

Application		
Function principle		Diffuse reflection sensor
Detection zone		
Range with fibre optic amplifier type		OKF; OUF
OKF		
Range fibre optics	[mm]	6
OUF		
Range fibre optics	[mm]	6
Operating conditions		
Ambient temperature	[°C]	-20...150
Mechanical data		
Version of sensing head		straight
Sensing head diameter	[mm]	1
Sensing head length	[mm]	5
Total length	[mm]	2500
Min. bending radius	[mm]	20
Fibre material		glass
Fibre head material		stainless steel (303/1.4305)

E20698



Fibre optic diffuse reflection sensor

FT-00-M-V-E1/2,5M

Fibre sheath material	metal silicone
Remarks	
Pack quantity	1 pcs.