


# E20060



## Fibre optic through-beam sensor

FE-00-P-A-E2,5

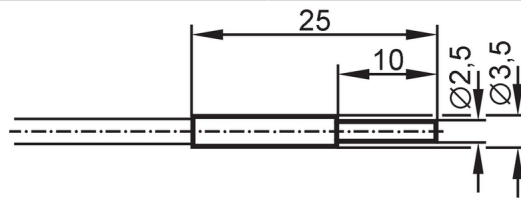

Application	
Function principle	Through-beam sensor
Application	Small bending radius
Detection zone	
Range with fibre-optic amplifier type	OKF; OOF; OUF
OKF	
Range of fibre optics [mm]	120
OOF	
Range of fibre optics [mm]	400
OUF	
Range of fibre optics [mm]	120
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Weight [g]	53.5
Version of sensing head	straight
Sensing head diameter [mm]	2.5
Sensing head length [mm]	10
Total length [mm]	600
Min. bending radius [mm]	10
Fibre arrangement	●
Materials	Adapter: PPE
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	PVC
Accessories	
Items supplied	E20106
Remarks	
Pack quantity	1 pcs.