


E20228



Fibre optic through-beam sensor

FE-00-P-A-R3

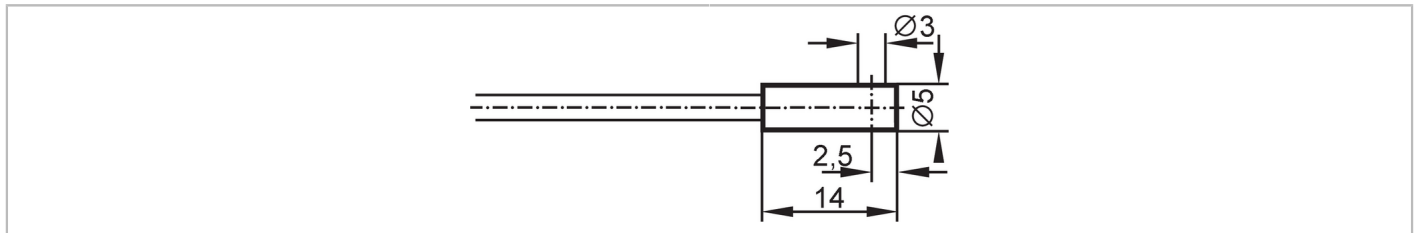

Application	
Design	90° deflection of the light beam
Function principle	Through-beam sensor
Application	For use in industrial environments
Detection zone	
Range with fibre-optic amplifier type	OKF; OUF; OOF
OKF	
Range of fibre optics [mm]	120
OOF	
Range of fibre optics [mm]	400
OUF	
Range of fibre optics [mm]	120
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Weight [g]	54.5
Version of sensing head	angled
Sensing head diameter [mm]	5
Sensing head length [mm]	14
Total length [mm]	600
Min. bending radius [mm]	20
Fibre arrangement	●
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	PVC
Accessories	
Items supplied	E20104
Remarks	
Pack quantity	1 pcs.