




Fibre optic through-beam sensor

FE-00-P-A-E2,5/2,5M

Article no longer available - archive entry

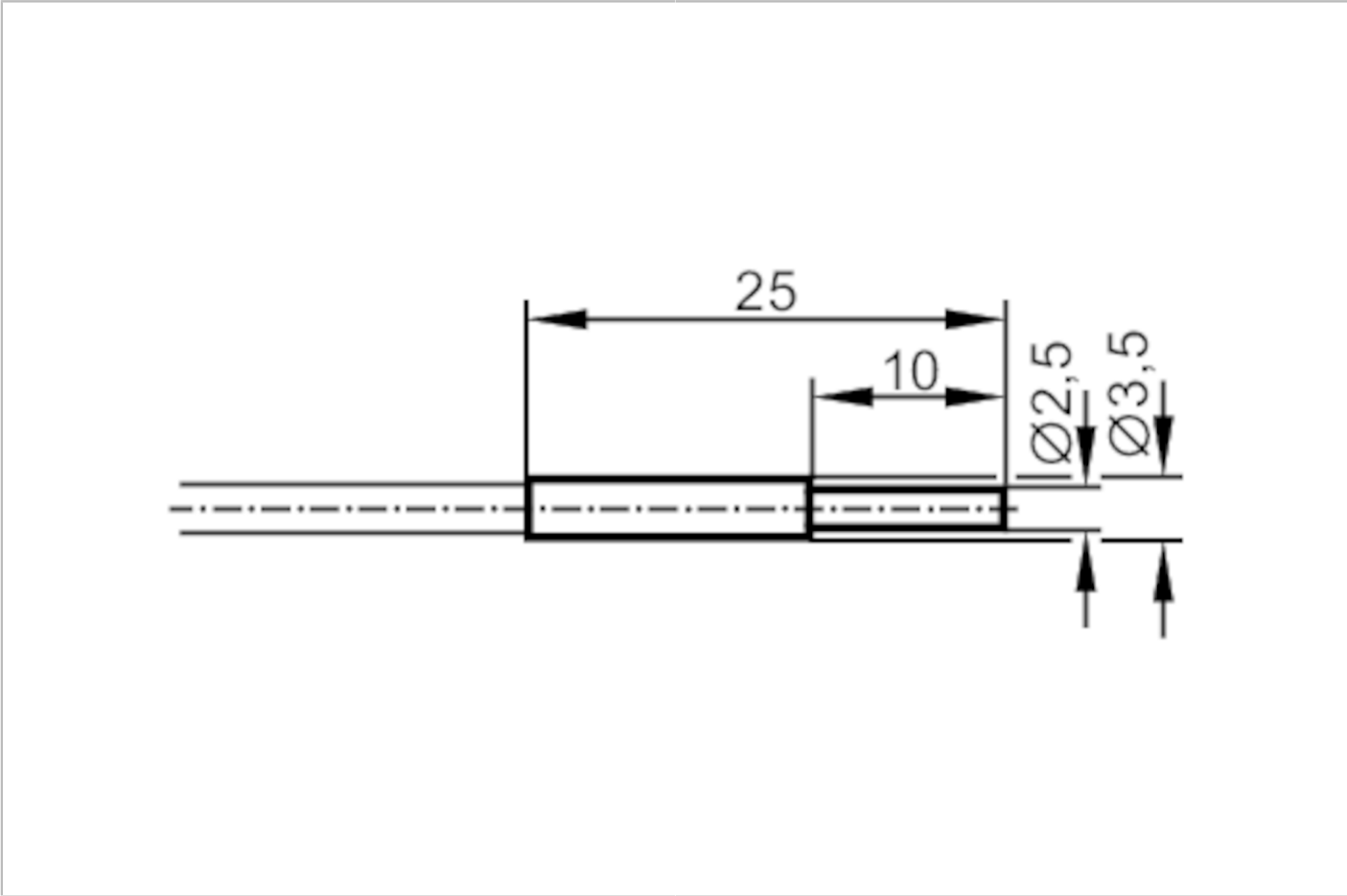

Application		
Function principle		Through-beam sensor
Detection zone		
Range with fibre-optic amplifier type		OKF; OUF
OKF		
Range of fibre optics	[mm]	85
OUF		
Range of fibre optics	[mm]	85
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Version of sensing head		straight
Sensing head diameter	[mm]	2.5
Sensing head length	[mm]	10
Total length	[mm]	2500
Min. bending radius	[mm]	10
Materials		Adapter: PPE
Fibre material		glass

E20359



Fibre optic through-beam sensor

FE-00-P-A-E2,5/2,5M

Fibre head material	aluminium
Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.