


T-piece with progressive ring fitting

T-PIECE QL28-18-28/VA

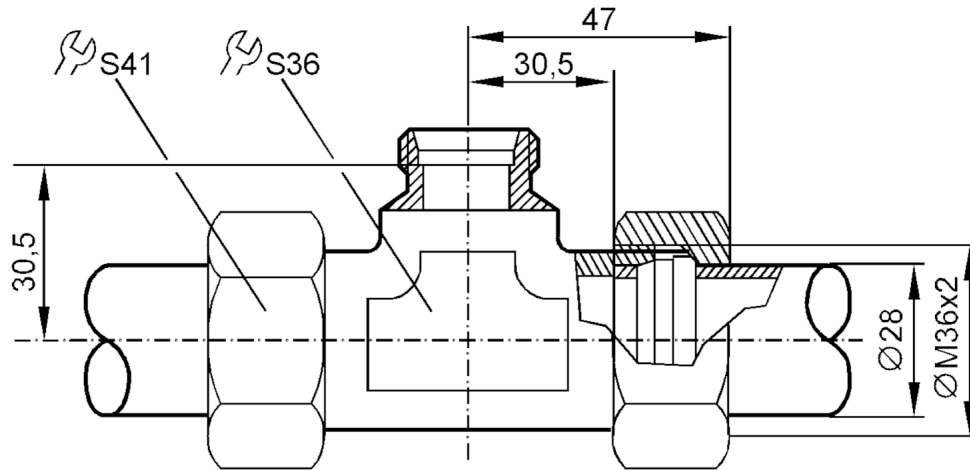

Application	
Design	for sensors and adapters with process connection M26x1,5
Application	for industrial applications
Media	liquids and gases
Pressure rating [bar]	160
Tests / approvals	
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.
Mechanical data	
Weight [g]	569.8
Type of mounting	Recommendation: precision steel pipes 28 x 1,5 DIN 2391/ISO 3304
Materials (wetted parts)	housing: stainless steel (316Ti/1.4571)
Sensor connection	M26 x 1,5
Process connection	Ø 28 mm
Accessories	
Accessories (optional)	Adapter: 1 x M18 x 1,5, for direct connection of flow sensors, E40104
Remarks	
Remarks	Use a lubricating paste which is suitable and approved for the application
	Observe the notes on the installation of progressive ring fittings
Pack quantity	1 pcs.