


E60122



Wirable socket

SDOGK120MKRFGSG

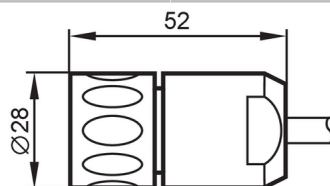

Application

Application Industrial applications / factory automation

Electrical data

Operating voltage [V] 4.5...30 DC

Operating conditions

Ambient temperature [°C] -40...125

Protection IP 67

Mechanical data

Weight [g] 43

Dimensions [mm] 28 x 28 x 52

Moulded-body material brass / PA 6.6, in plastic sheath

Material nut brass / PA 6.6, in plastic sheath

Remarks


Pack quantity 1 pcs.

Electrical connection

soldering: ...1 mm²

Electrical connection - socket

Connector: 1 x M23, straight; Contacts: 12; Moulded body: brass / PA 6.6, in plastic sheath, black; Locking: brass / PA 6.6, in plastic sheath

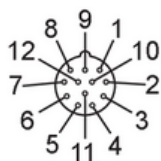

E60122



Wirable socket

SDOGK120MKRFKSG

Connection

