


## Connecting cable with socket

ADOGK170MSL0020B17

Article no longer available - archive entry

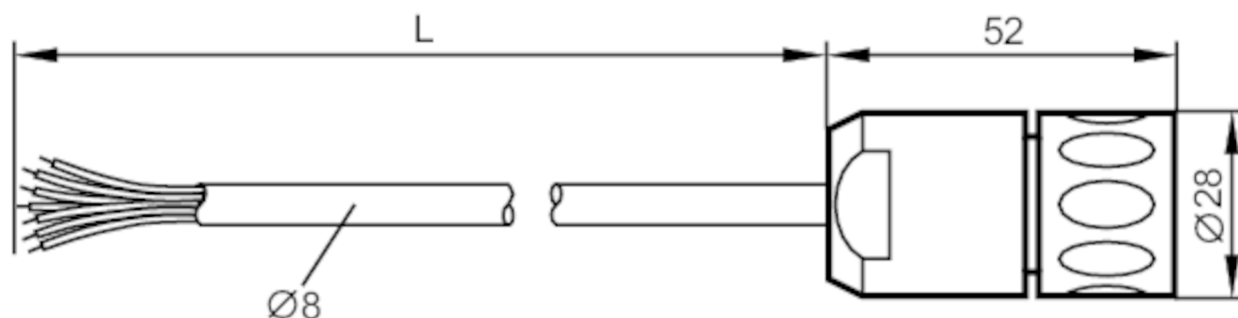

## Electrical data

Operating voltage	[V]	4.5...30 DC
-------------------	-----	-------------

## Operating conditions

Ambient temperature	[°C]	-10...85
---------------------	------	----------

Protection		IP 67
------------	--	-------

## Mechanical data

Weight	[g]	2000
--------	-----	------

Dimensions	[mm]	28 x 28 x 52
------------	------	--------------

Materials		brass in plastic sheath; PA 6.6 black
-----------	--	---------------------------------------

Moulded-body material		brass / PA 6.6, in plastic sheath
-----------------------	--	-----------------------------------

Material nut		brass, in plastic sheath / PA 6.6, in plastic sheath
--------------	--	--

## Remarks

Pack quantity		1 pcs.
---------------	--	--------

# E60191



## Connecting cable with socket

ADOGK170MSL0020B17


### Electrical connection

Cable: 20 m, PUR, Ø 8 mm; 13 x 0.14 mm<sup>2</sup> + 4 x 0.5 mm<sup>2</sup>

### Electrical connection - socket

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: brass, in plastic sheath

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: PA 6.6, in plastic sheath

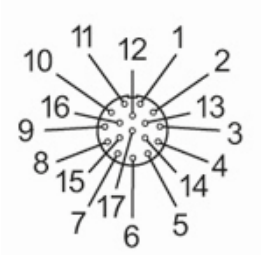

### Connection

1	BU
2	BK
3	RD
4	WH
5	GN
6	BN
7	BN/GN
8	VT
9	YE
10	WH/GN
11	screen
12	BU/BK
13	RD/BK
14	GY
15	GN/BK
16	YE/BK
17	PK

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow
screen =	screen